



NEMA SIZE 2 STARTER
3-POLE POLYPHASE - 600 VAC, 50-60 HZ

COIL VOLTAGE CODE (1)	VOLTAGE	
	60 HZ	50 HZ
V01	24	-
V02	120	110
V08	208	-
V03	240	220
V06	480	440
V07	600	550
V99	SPECIFY	SPECIFY

ELECTRICAL CLEARANCE/WIRE BENDING SPACE

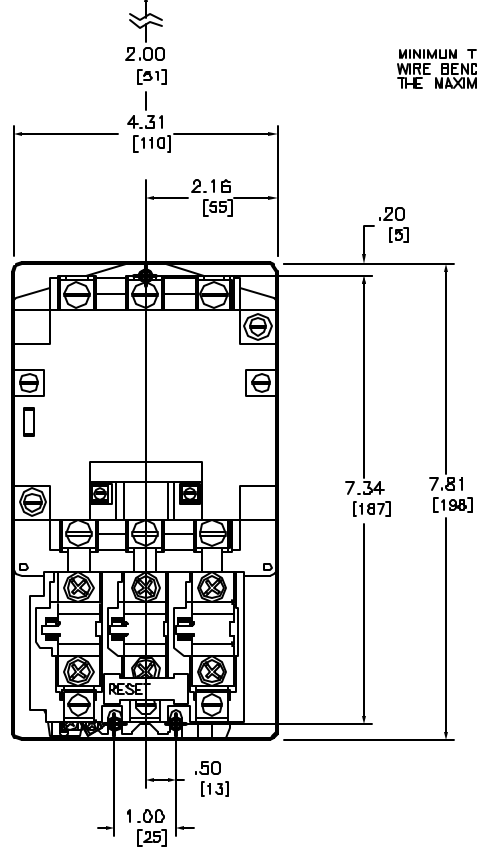

MINIMUM TO WALL OR BARRIER TO INSURE ADEQUATE WIRE BENDING SPACE TO LUG SURFACE WHEN THE MAXIMUM WIRE SIZE IS USED. REF. NEC 430-10

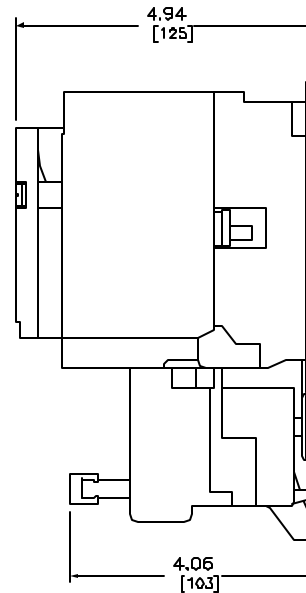

Catalog Number: 8536-S001(1)
 Ratings: SEE CHART
 UL File/CCN: E78361/NLX
 CSA File/Class: LR80906/3211 0
 Meets Standards: -
 Weight: 7.75 lbs
 Wire Size: POWER - #14-4, CONTROL - #16-#12
 Terminal torque: 50 LB/IN
 Mounting Hwd.: (3) #10 screws

DUAL DIMENSIONS: INCHES
MILLIMETERS

NEMA SIZE 2 STARTER
CLASS 8536 TYPE S001(1)



DWG# E0303101-01
NO.