


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

HMIZKB1

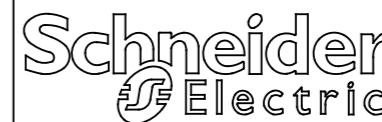

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

NEMA Protection:	Type 4X
Storage Temperature:	-20 to 60°C (-4 to 140°F)
Operating Temperature:	0 to 55°C (32 to 131°F)
IP Protection:	IP65
Humidity:	10% to 90% non-condensing
Voltage:	DC 5V, Powered by USB
Connection:	USB 2.0
Power:	0.75W

Specification:

Description:	Magelis USB Keyboard - 22 mm – 20 keys
Certifications:	CE, UL/CUL listed, RCM, EAC
Hazardous Locations:	Class I Division 2 Groups A/B/C/D
Buttons:	20 keys (12 programmable)
LED Indicators:	14 LEDs (12 programmable)
Standards:	CSA C22.2 No 142, EN 61000-6-2, EN 61000-6-4, ROHS directive 2002/95/EC, UL 508, EMC 2004/108/EC, WEEE directive 2002/96/EC, CSA C22.2 No 213, RoHS China SJ/T 11363-2006, ANSI/ISA 12.12.01