


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

LADN133

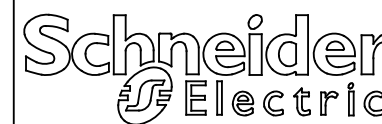

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Contact Rating:	A600, Q600 10A
UL File/CCN:	E164862 / NKCR
CSA File:	LR43364 3211 04
Meets Standard:	IEC 60947-5-1
Weight:	0.14 lb (0.07 kg)
Termination Method:	Spring Terminal
Control Wire Size:	#10 - #18 AWG
Control Terminal Torque:	N/A
Mounting Hardware:	TeSys D IEC AC or DC Contactor or Control Relay

Description:
 Type:

TeSys D IEC Contact Block - Front Mount - 1NO, 3NC
 TeSys D IEC Contactor and Control Relay Accessory

Specification: