


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

LADR4

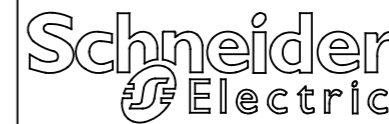

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Contact Rating: A600, Q600 10A
 UL File/CCN: E164862 / NKCR
 CSA File: LR43364 3211 04
 Meets Standard: IEC 60947-5-1
 Weight: 0.17 lb (0.08 kg)
 Termination Method: Screw Terminal
 Control Wire Size: #10 - #18 AWG
 Control Terminal Torque: 15 lb-in (1.7 Nm)
 Mounting Hardware: TeSys D IEC AC or DC Contactor or Control Relay

Description:
 Type:

TeSys D IEC Off-Delay Timer - Front Mount - 10 to 180 Sec
 TeSys D IEC Contactor and Control Relay Accessory

Specification: