


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**LADS2**

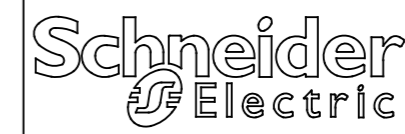

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Contact Rating: A600, Q600 10A  
 UL File/CCN: E164862 / NKCR  
 CSA File: LR43364 3211 04  
 Meets Standard: IEC 60947-5-1  
 Weight: 0.17 lb (0.08 kg)  
 Termination Method: Screw Terminal  
 Control Wire Size: #10 - #18 AWG  
 Control Terminal Torque: 15 lb-in (1.7 Nm)  
 Mounting Hardware: TeSys D IEC AC or DC Contactor or Control Relay

**Specification:**

Description: TeSys D IEC On-Delay Timer - Front Mount - 1 to 30 Sec  
 Type: TeSys D IEC Contactor and Control Relay Accessory