


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

LC1D25T7

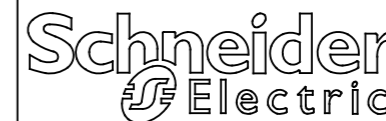

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Rating: 600V / 25A
 UL File/CCN: E164862 / NLDX
 CSA File: LR43364 3211 04
 Meets Standards: IEC 60647-4
 Weight: 0.82 lb (0.37 kg)
 Termination Method: Screw Clamp
 Wire Size: Power: #6 - #14 AWG
 Control: #10 - #18 AWG
 Terminal torque: Power: 20 lb-in (2.5 Nm)
 Control: 15 lb-in (1.7 Nm)
 Mounting Hwd.: 35mm DIN Rail, #8 screw

Specification:

Description: TeSys D IEC Contactor - 25A - Vac Coil
 Type: TeSys D IEC Contactor - 25A - 480Vac Coil
 Voltages Code: T7 at 480Vac 50/60 Hz

Coil Consumption: Inrush 70 VA
 Sealed 7.5 VA

Single Phase			Three Phase		
115V	230V	200V	230V	460V	575V
2 HP	3 HP	7.5 HP	7.5 HP	15 HP	20 HP