


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**LP4K1210BW3**

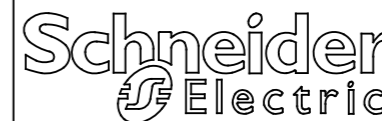

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Rating: 600V / 12A  
 UL File/CCN: E164353 / NKCR  
 CSA File: LR43364 3211 03  
 Meets Standards: IEC 60647-1-1  
 Weight: 0.40 lb (0.18 kg)  
 Termination Method: Screw Clamp  
 Wire Size: Power: #12 - #18 AWG  
 Control: #12 - #18 AWG  
 Terminal torque: Power: 7 lb-in (0.8 Nm)  
 Control: 7 lb-in (0.8 Nm)  
 Mounting Hwd.: 35mm DIN Rail, 4mm screw

**Specification:**

Description: TeSys K Non-reversing Contactor  
 Type: TeSys K IEC Contactor - 12A - 24Vdc Coil  
 Voltages Code: BW3 at 24VDC

Coil Consumption: Inrush 1.8 W  
 Sealed 1.8 W

| Single Phase |        | Three Phase |      |        |       |
|--------------|--------|-------------|------|--------|-------|
| 115V         | 230V   | 200V        | 230V | 460V   | 575V  |
| 0.5 HP       | 1.5 HP | 3 HP        | 3 HP | 7.5 HP | 10 HP |