



TOP POWER ENTRY 90mm DIA

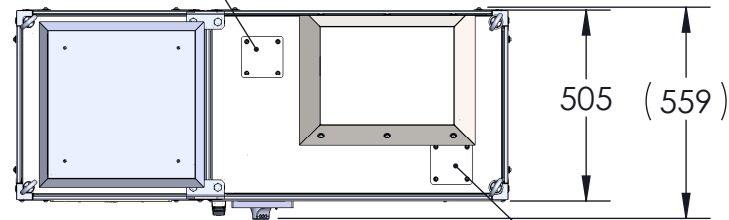

505 (559)

TOP COMMUNICATIONS & CT's 50x50mm OPENING ENTRY

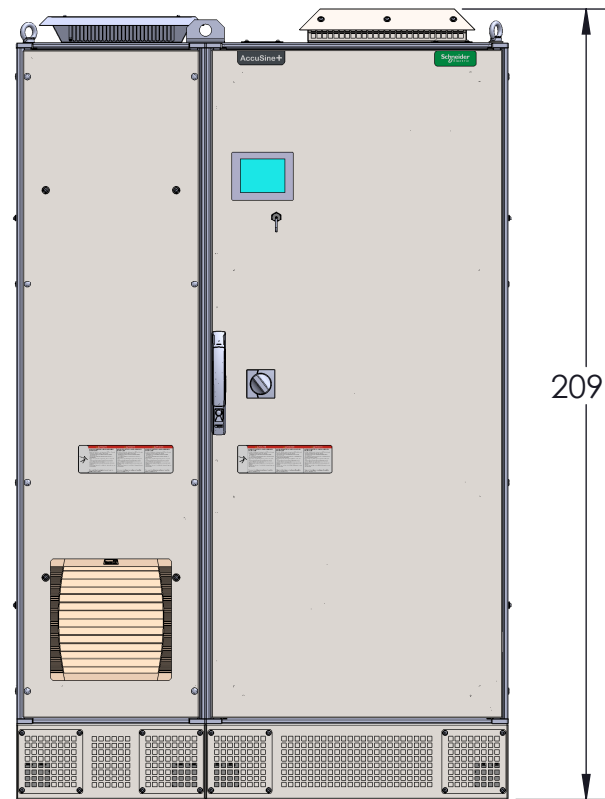


2091

1300

Ø 90 BOTTOM POWER ENTRY

BOTTOM ENTRY COMMUNICATIONS 50X50mm OPENING

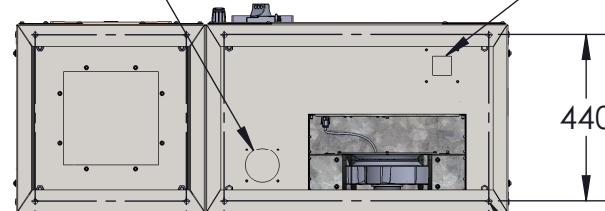

440

400

700

1200

Ø 13 FLOOR ANCHOR

NHA5990500 SMALL ENCLOSURE 600-690V IP54/N12

PCSP047D6N12	AccuSine PCS+ 47A, 600 VAC N12	HRB37663
EVCP047D6N12	AccuSine PFV+ 47A, 600 VAC N12	HRB37664
PCSP047D6IP54	AccuSine PCS+ 47A, 600 VAC IP54	HRB37666
EVCP047D6IP54	AccuSine PFV+ 47A, 600 VAC IP54	HRB37667
PCSP094D6N12	AccuSine PCS+ 94A, 600 VAC N12	HRB49236
EVCP094D6N12	AccuSine PFV+ 94A, 600 VAC N12	HRB49237
PCSP094D6IP54	AccuSine PCS+ 94A, 600 VAC IP54	HRB49238
EVCP094D6IP54	AccuSine PFV+ 94A, 600 VAC IP54	HRB49239
PCSP080D7N12	AccuSine PCS+ 80A, 690 VAC N12	HRB49255
PCSP080D7IP54	AccuSine PCS+ 80A, 690 VAC IP54	HRB49256
EVCP080D7N12	AccuSine PFV+ 80A, 690 VAC N12	HRB49257
EVCP080D7IP54	AccuSine PFV+ 80A, 690 VAC IP54	HRB49258
PCSP040D7N12	AccuSine PCS+ 40A, 690 VAC N12	HRB37675
PCSP040D7IP54	AccuSine PCS+ 40A, 690 VAC IP54	HRB37676
EVCP040D7N12	AccuSine PFV+ 40A, 690 VAC N12	HRB37679
EVCP040D7IP54	AccuSine PFV+ 40A, 690 VAC IP54	HRB37680

	Scale: N/A	Tolerancing Standard: ISO8015	Units of Measure: mm
	SMALL ENCLOSURE 600-690V IP54/N12		
	SMALL ENCLOSURE 600-690V IP54/N12		
Number: NHA5990500		Revision: 00	Sheet: 1 OF 1

All information and data contained in this document are the exclusive property of Schneider Electric Industries SAS and may neither be used nor disclosed without its prior written consent.

State:

Released for Manufacturing
Printed on 2015/07/09