


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ZB4BC38013RA

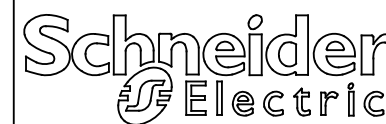

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL Cert.:	E164353 CCN NKCR
CSA Cert.:	LR44087 Class 3211 03
CE Cert.:	CE per IEC
IP Protection:	P 66 IP 69K
NEMA Protection:	NEMA 4, 12, 13
IK Protection:	IK03
Ambient Air Temp. (for storage):	-40 to +85 °C
Ambient Air Temp. (for operation):	-40 to +70°C
Electric Shock Protection:	Class I
Washdown Resistance (in Pa):	90 Pa

Specification:

Description:	22MM HARSH PB, GREEN, W/ MARKING, ROTATE 90°
Mechanical Durability (in operating cycles):	3000000
Vibration Resistance:	5 gn
Mechanical Shock Resistance:	30 gn
Color:	Green
Button Marking:	w/, rotate 90°