


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

ZB4BC58009

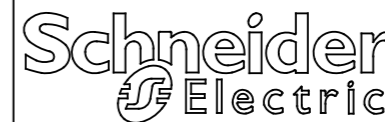

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL Cert.: E164353 CCN NKCR
 CSA Cert.: LR44087 Class 3211 03
 CE Cert.: CE per IEC
 IP Protection: P 66 IP 69K
 NEMA Protection: NEMA 4, 12, 13
 IK Protection: IK03
 Ambient Air Temp. (for storage): -40 to +85 °C
 Ambient Air Temp. (for operation): -40 to +70°C
 Electric Shock Protection: Class I
 Washdown Resistance (in Pa): 90 Pa

Specification:

Description: 22MM HARSH PB, YELLOW, W/ MARKING
 Mechanical Durability (in operating cycles): 3000000
 Vibration Resistance: 5 gn
 Mechanical Shock Resistance: 30 gn
 Color: Yellow
 Button Marking: w/