


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ZB4BC68026RA

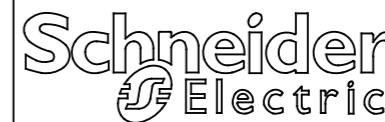

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

| | |
|------------------------------------|-----------------------|
| UL Cert.: | E164353 CCN NKCR |
| CSA Cert.: | LR44087 Class 3211 03 |
| CE Cert.: | CE per IEC |
| IP Protection: | P 66 IP 69K |
| NEMA Protection: | NEMA 4, 12, 13 |
| IK Protection: | IK03 |
| Ambient Air Temp. (for storage): | -40 to +85 °C |
| Ambient Air Temp. (for operation): | -40 to +70°C |
| Electric Shock Protection: | Class I |
| Washdown Resistance (in Pa): | 90 Pa |

Specification:

| | |
|--|--|
| Description: | 22MM HARSH PB, DARK BLUE, W/ MARKING, ROTATE 90° |
| Mechanical Durability (in operating cycles): | 3000000 |
| Vibration Resistance: | 5 gn |
| Mechanical Shock Resistance: | 30 gn |
| Color: | Dark Blue |
| Button Marking: | w/, rotate 90° |