


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**ZB4BS84430**

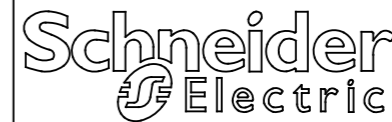

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

UL Listed:	Yes
UL File:	UL 746C
CSA Approval:	Yes
CSA File:	
CE:	Yes
RoHS:	Yes
Bezel Material:	Zamak (die-cast zinc), right chrome plated
NEMA / IP Rating:	NEMA 1/2/3/4/4X/13; IP66
Key Number:	n/a
Key Removal:	n/a
Max. # of Contact Blocks:	4
Button Marking:	EMO

**Specification:**

Description:	22mm EMO Push Button
Operator Type:	Non-Illuminated
Operator Action:	Turn to Release
Button Type:	40 mm knob
Bezel Type:	Metal
Color:	Red
Head Type:	Round