


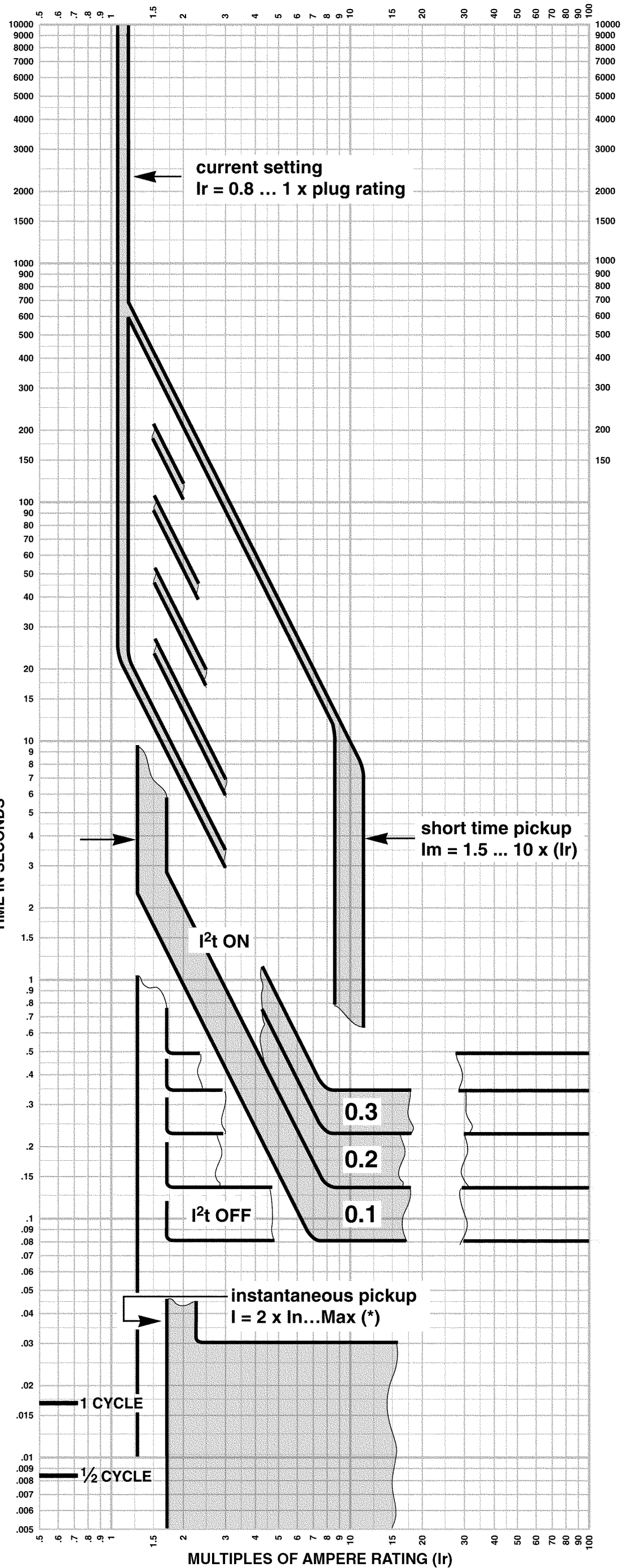

MULTIPLES OF AMPERE RATING (I<sub>r</sub>)




MASTERPACT UNIVERSAL POWER CIRCUIT BREAKER  
CHARACTERISTIC TRIP CURVE NO. 632-10

CIRCUIT BREAKER INFORMATION

Circuit Breaker Prefix	Continuous Ampere Rating	Maximum AC Voltage	Number of Poles
MP STR 58U	250-6300	600	3

This curve is to be used for application and coordination purposes only. The **EZ-AMP** overlay feature at the bottom of the page should be used during coordination studies.

All time/current characteristic curve data is based on 40°C ambient cold start. Terminations are made with conductors of appropriate length and ratings.

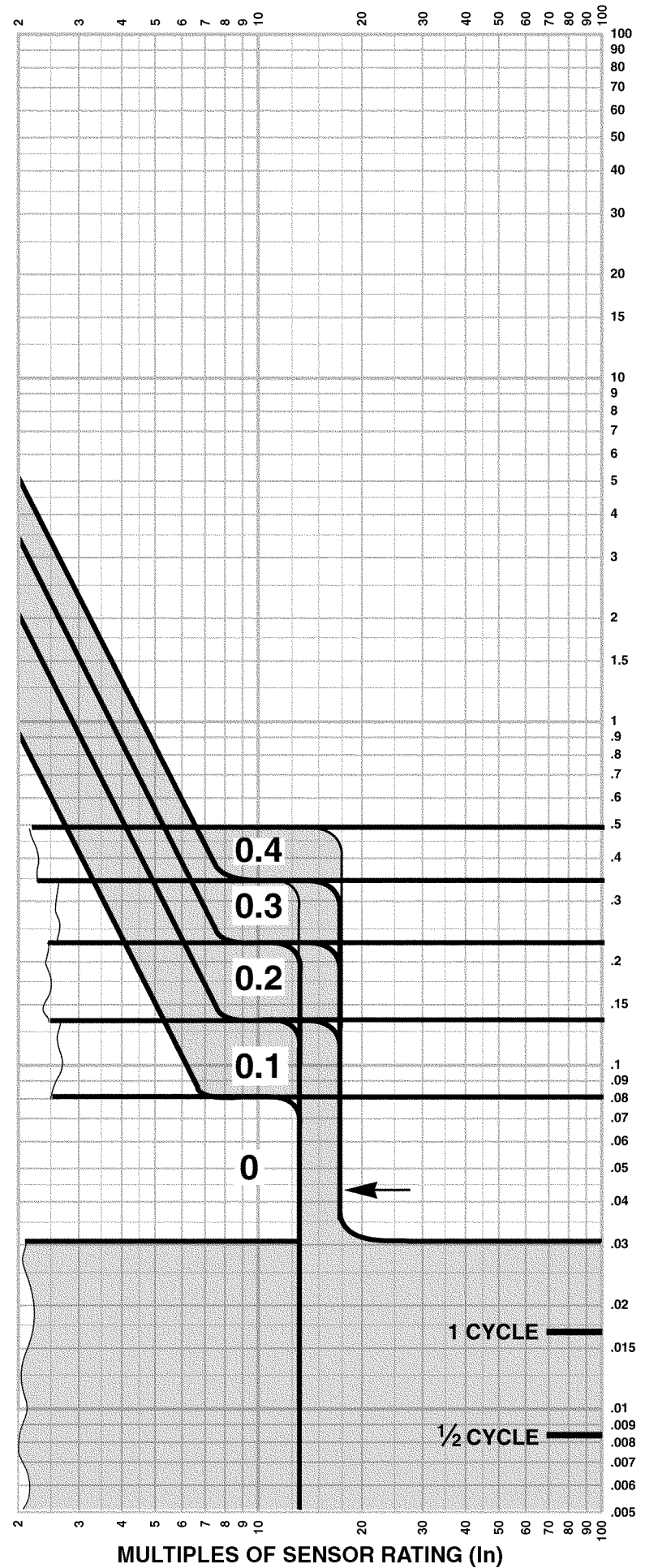

Max (\*) (OFF position on H1 type)

rating	I <sub>n</sub> (A) ≤	630	800/1000	1200/1600	2000	2500	3000/3200	4000/5000/6300
max. Inst=I <sub>n</sub> x...		28	28	24	20	14	12	10

SQUARE D®

©1996 Square D

EZ-AMP™