




STP300

Immersion pipe temperature transmitter
Dykrörs temperaturtransmitter
Einschraubtemperaturmeßumformer
Convertisseur de sonde de plongee
Transmisor de temperatura entornillado
Transformatore temperatura a vite


OFL-4190-001

Instruction
Montageanvisning
Bedienungsanleitung
Instructions d'installation
Instrucciones de empleo
Istruzioni per installazioni


1.

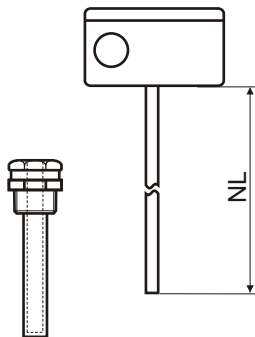


2.

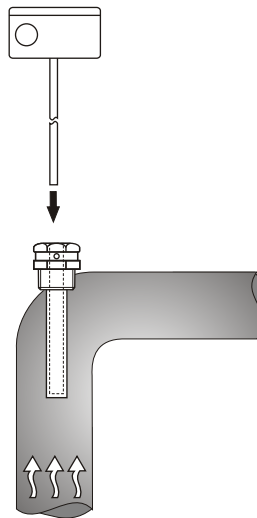


3.

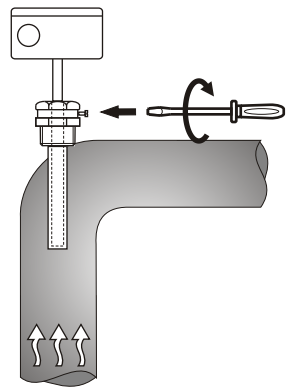

4.

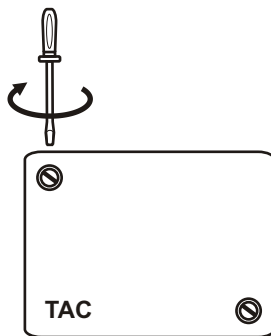


5.

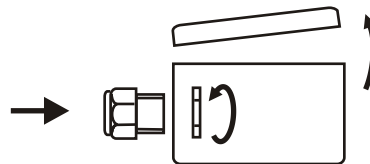

6.

4...20mA

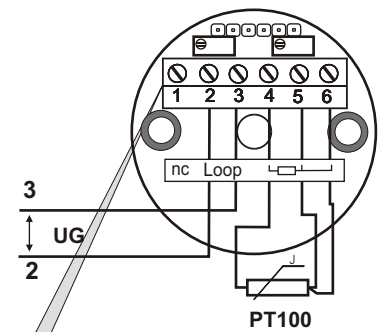

UG=15...36 V DC

