


Flat tight connections

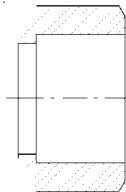

Valve+MZ88T actuator dimensions	DN	A	B	C
mm (in)				
VZ28-15-0,25 VZ28-15-0,4 VZ28-15-0,6 VZ28-15-1 VZ28-15-1,6	1/2"	52 (2.04)	95,5 (3.75)	19,5 (0.76)
VZ28-20-2,5 VZ28-20-4,0 VZ28-20-6,0	3/4"	56 (2.2) 78 (3)	96.5 (3.8)	20.5 (0.8)
VZ38-15-0,25 VZ38-15-0,4 VZ38-15-0,6 VZ38-15-1 VZ38-15-1,6	1/2"	52 (2.04)	101 (3.97)	25 (0.98)
VZ38-20-2,5 VZ38-20-4,0 VZ38-20-6,0	3/4"	56 (2.2) 78 (3)	110 (4.33) 111.5 (4.4)	34 (1.33) 35.5 (1.4)
VZ48-15-0,25 VZ48-15-0,4 VZ48-15-0,6 VZ48-15-1 VZ48-15-1,6	1/2"	52 (2.04)	127 (5)	40 (1.57)
VZ48-20-2,5 VZ48-20-4,0 VZ48-20-6,0	3/4"	56 (2.2) 78 (3)	139 (5.47) 150 (5.9)	50* (1.97) 44 (1.73)

* 50 mm (1.97) for p/n 741-0435-000
44 mm (1.73) for p/n 741-0435-010

9 PRESSURE DROP DIAGRAM

